
 


**linear drive**  
**DGO-1 5/8"- -PPV-A-B**  
Part number: 15232

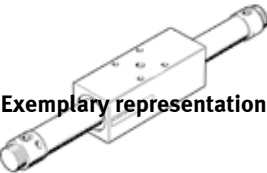

For proximity sensing, rodless, with magnetic coupling.



Exemplary representation

**Data sheet**

Feature	Value
Stroke	0.04 ... 157 "
Piston diameter	1 5/8"
Cushioning	PPV: Pneumatic cushioning adjustable at both ends
Guide	Plain-bearing guide
Driver principle	force-locking (magnet)
Operating pressure	1.3 ... 7 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-20 ... 60 °C
Cushioning length	23 mm
Pneumatic connection	1/4 NPT