


manifold sub-base with 90° connections NAVW-1/4-NPT-1

Part number: 152792

FESTO

With port pattern as per DIN ISO 5599/1, for manifold assembly,
connections at side and underneath.

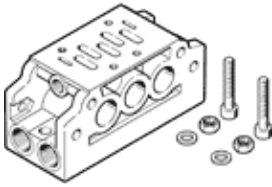

Data sheet

Feature	Value
Width	110 mm
Operating pressure	0 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
PWIS conformity	VDMA24364-B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Mounting method for sub-base	with through hole
Pilot air port 12	1/8 NPT
Pilot air port 14	1/8 NPT
Pneumatic connection, port 1	1/4 NPT
Pneumatic connection, port 2	1/4 NPT
Pneumatic connection, port 4	1/4 NPT