


manifold sub-base with 90° connections

NAVW-3/8-NPT-2

Part number: 152793

FESTO

With port pattern as per DIN ISO 5599/1, for manifold assembly, connections at side and underneath.

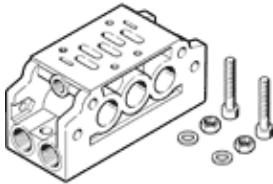

Data sheet

Feature	Value
Width	135 mm
Operating pressure	0 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Mounting method for sub-base	with through hole
Pilot air port 12	1/8 NPT
Pilot air port 14	1/8 NPT
Pneumatic connection, port 1	3/8 NPT
Pneumatic connection, port 2	3/8 NPT
Pneumatic connection, port 4	3/8 NPT