 



pressure gauge MA-15-10-QS-4

Part number: 153383

FESTO

With display unit in bar and psi.

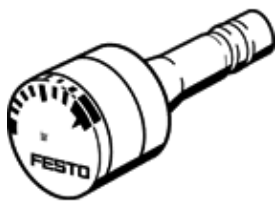

Data sheet

| Feature | Value |
|------------------------------------|---|
| Indicating range [bar] | 0 ... 10 bar |
| Nominal size of pressure gauge | 15 |
| Design structure | Bourdon tube pressure gauge without measuring mechanism |
| Mounting type | Line installation |
| Operating medium | Inert gases Neutral fluids |
| Operating pressure MPa | 0 ... 1 MPa |
| Operating pressure | 0 ... 10 bar 0 ... 145 psi |
| Alternating load factor | 0.66 |
| Measurement accuracy class | 5 |
| Protection class | IP53 |
| Medium temperature | -20 ... 60 °C |
| Ambient temperature | -20 ... 60 °C |
| PWIS conformity | VDMA24364-B2-L |
| Materials note | Conforms to RoHS |
| Position of connection | Rear side central |
| Pneumatic connection | QS-4 |
| Materials in contact with media | Brass |
| Material of threaded plug | Brass |
| Material housing | Steel |
| Material screen | PC |
| Housing colour | Black |
| Product weight | 10 g |
| Note on operating and pilot medium | No acetylene No oxygen |