


ball valve QHS-QS-6

Part number: 153485

FESTO

With QS plug connector.
This type is suitable for vacuum.

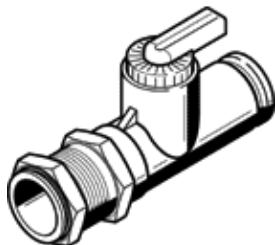

Data sheet

Feature	Value
Valve function	2/2 bistable
Pneumatic connection, port 1	QS-6
Pneumatic connection, port 2	QS-6
Type of actuation	manual
Mounting type	with lock nut
Standard nominal flow rate	528 l/min
Nominal size	4 mm
Operating pressure MPa	-0.1 ... 1 MPa
Operating pressure	-1 ... 10 bar
Ambient temperature	0 ... 60 °C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Sealing principle	soft
Design structure	Ball valve
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Product weight	16.5 g
Materials note	Conforms to RoHS