


# ball valve

## QH-QS-4-1/8

Part number: 153486

FESTO

with QS push-in connector.  
This type is suitable for vacuum.

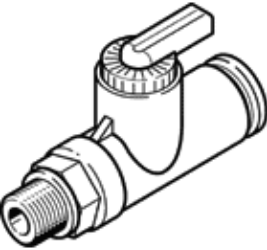

### Data sheet

Feature	Value
Valve function	2/2 bistable
Pneumatic connection, port 1	R1/8
Pneumatic connection, port 2	QS-4
Type of actuation	manual
Mounting type	Threaded
Standard nominal flow rate	235 l/min
Nominal size	2.5 mm
Operating pressure MPa	-0.1 ... 1 MPa
Operating pressure	-1 ... 10 bar
Ambient temperature	0 ... 60 °C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Sealing principle	soft
Design structure	Ball valve
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Product weight	14 g
Materials note	Conforms to RoHS