

# Push-in L-fitting QSL-1/8-5/32-U


Part number: 153639

FESTO

rotatable by 360°, male thread with external hexagon.

This product is only available if ordered from the Festo Corporation, USA.

Products to be discontinued. Available until 2011.

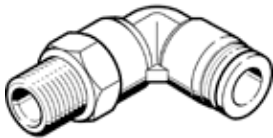

## Data sheet

| Feature                                  | Value   |
|--|---|
| Size                                     | Standard  |
| Nominal size                             | 2.3 mm  |
| Type of seal on screw-in stud            | coating   |
| Assembly position                        | Any   |
| Container size                           | 1   |
| Design structure                         | Push/pull principle                             |
| Operating pressure                       | -0.95 ... 10 bar                                |
| Temperature dependent operating pressure | -0.95 ... 10 bar                                |
| Operating medium                         | Filtered compressed air<br>Vacuum               |
| Corrosion resistance classification CRC  | 1   |
| Ambient temperature                      | -10 ... 60 °C                                   |
| Authorisation                            | Germanischer Lloyd                              |
| Max. tightening torque                   | 8 Nm  |
| Pneumatic connection                     | NPT1/8-27<br>for tubing, 5/32" outside diameter |
| Colour of release ring                   | Grey  |
| Materials note                           | Conforms to RoHS                                |
| Materials information, housing           | PBT   |
| Release ring material data               | POM   |
| Materials information for tubing seal    | NBR   |
| Hose clamping segment material data      | High alloy steel, non-corrosive                 |