


multiple distributor QSQ-3/16T-5/32-U

Part number: 153814

FESTO

360° orientable, 4 outlets.

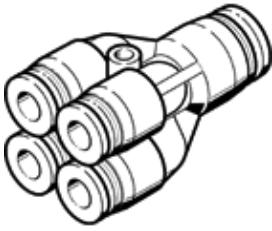

Data sheet

Feature	Value
Size	Standard
Nominal size	1.4 mm
Assembly position	Any
Design structure	Push/pull principle
Container size	1
Operating pressure complete temperature range	-0.95 ... 10 bar
Maritime classification	see certificate
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Number of outputs	4
Number of supply lines	1
Pneumatic connection, port 1	for tubing, 3/16" outside diameter
Pneumatic connection, port 2	for tubing, 5/32" outside diameter
Colour of release ring	Grey
Materials note	Conforms to RoHS
Material housing	PBT
Material release ring	POM
Material of tubing seal	NBR
Material of tube retaining claw	High alloy steel, non-corrosive