


Push-in L-connector QSML-1/8T-U

Part number: 153913

FESTO

This product is only available if ordered from the Festo Corporation, USA.
Type to be discontinued. Available until 2013. See Support Portal for
alternative products.

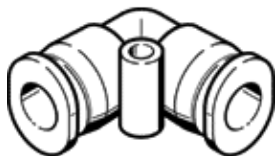

Data sheet

| Feature | Value |
|---|--|
| Size | Mini |
| Nominal size | 2.5 mm |
| Assembly position | Any |
| Container size | 1 |
| Design structure | Push/pull principle |
| Operating pressure complete temperature range | -0.95 ... 10 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 1 |
| Ambient temperature | -10 ... 60 °C |
| Authorisation | Germanischer Lloyd |
| Product weight | 2 g |
| Pneumatic connection, port 1 | for tubing, 1/8" outside diameter |
| Pneumatic connection, port 2 | for tubing, 1/8" outside diameter |
| Colour of release ring | Grey |
| Materials note | Conforms to RoHS |
| Materials information, housing | PBT |
| Release ring material data | POM |
| Materials information for tubing seal | NBR |
| Hose clamping segment material data | High alloy steel, non-corrosive |