


swivel flange SUA-25

Part number: 157321

FESTO

For cylinders ADVU, AEVU; matching clevis foot mountings LBN or LN, LSN.

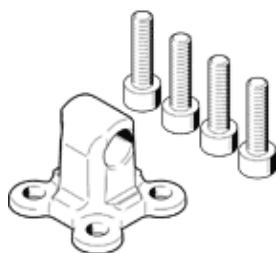

Data sheet

Feature	Value
Size	25
Assembly position	Any
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 ... 90 °C
Product weight	45 g
Materials note	Conforms to RoHS
Material mounting	Wrought Aluminium alloy
Material mounting pin	steel, galvanized
Material sleeve	Spring steel
Material bearing	Plastic
Material screws	Galvanised steel
Material lock	Spring steel
Material shaft	Steel With protective coating