


**timer**  
**PZVT-3-SEC**  
 Part number: 158495

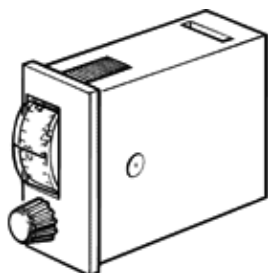

**Data sheet**

<b>Feature</b>	<b>Value</b>
Design structure	mechanical sequence counter with pneumatic drive
Switch-off pressure	$\leq 0.1$ bar
Operating pressure	2 ... 6 bar
Switch-on pressure	$\geq 1.6$ bar
Standard nominal flow rate	50 l/min
Adjustable delay times	0.2 ... 3 s
Setting accuracy	$\pm 0,3$ s
Pause period for reset	$\geq 200$ ms
Repetition accuracy, time setting	$\pm 0,1$ s
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation not possible
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP54 With protective cover and panel frame to IEC 60529
Ambient temperature	-10 ... 60 °C
Product weight	45 g
Mounting type	Front panel installation
Pneumatic connection	Female thread M5
Materials note	Conforms to RoHS
Material housing	ABS