

# lubricator

 

## LOE-3/4-D-MAXI

Part number: 159622  
Classic - do not use for new projects

FESTO

With metal bowl guard.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

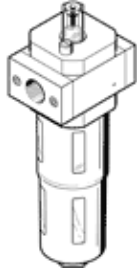

### Data sheet

| Feature                                   | Value   |
|---|---|
| Size                                      | Maxi  |
| Series                                    | D   |
| Assembly position                         | Vertical +/- 5°   |
| Design structure                          | proportional standard mist lubricator                                       |
| Max. oil capacity                         | 190 cm <sup>3</sup>   |
| Bowl guard                                | Metal bowl guard  |
| Operating pressure                        | 0 ... 16 bar  |
| Minimum flow rate for lubricator function | 10 l/min  |
| Standard nominal flow rate                | 8,400 l/min   |
| Operating medium                          | Compressed air in accordance with ISO8573-1:2010 [7:4:4]<br>Inert gases     |
| Note on operating and pilot medium        | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC   | 2 - Moderate corrosion stress   |
| PWIS conformity                           | VDMA24364-B1/B2-L   |
| Storage temperature                       | -10 ... 60 °C   |
| Air purity class at output                | Compressed air in accordance with ISO8573-1:2010 [7:4:-]<br>Inert gases     |
| Medium temperature                        | -10 ... 60 °C   |
| Ambient temperature                       | -10 ... 60 °C   |
| Product weight                            | 1,100 g   |
| Mounting type                             | with accessories  |
| Pneumatic connection, port 1              | G3/4  |
| Pneumatic connection, port 2              | G3/4  |
| Materials note                            | Conforms to RoHS  |
| Material bowl                             | PC  |