


air reservoir CRVZS-0.75

Part number: 160235

FESTO

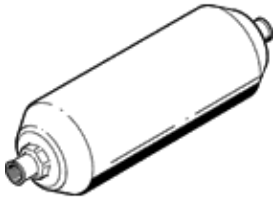

Data sheet

| Feature | Value |
|---|---|
| Volume | 0,75 l |
| Assembly position | Any |
| Conforms to standard | AD 2000 reference sheet |
| Operating pressure MPa | -0.095 ... 1.6 MPa |
| Operating pressure | -0.95 ... 16 bar -13.78 ... 232 psi |
| Authorisation | CRN TÜV |
| Certificate issuing department | TSSACRN0H17477.5C |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [-:~:] Nitrogen |
| Corrosion resistance classification CRC | 3 - High corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Food-safe | See Supplementary material information |
| Medium temperature | -10 ... 100 °C |
| Ambient temperature | -10 ... 100 °C |
| Max. tightening torque, connecting thread | 23 Nm |
| Product weight | 736 g |
| Mounting type | Fixing clips |
| Pneumatic connection | G1/4 |
| Materials note | Conforms to RoHS |
| Material of air reservoir | High alloy steel, non-corrosive |
| Material fixing clips | High alloy steel, non-corrosive |