 



Flow GRLO-M5-LF-B

Part number: 161408

FESTO

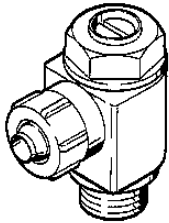

Datasheet

Feature	Value
Function	Flow control
Function restrictor	Adjustable
Actuating component	Screw
Type of mounting	Screw-in
Nominal size flow control	2 mm
Air connection type 1	Male thread
Air connection type 1	Female thread
Thread for port 1	M 5
Thread for port 2	M 5
Operating pressure min.	0 bar
Operating pressure max.	10 bar
Minimum ambient temperature	-10 °C
Maximum ambient temperature	60 °C
Minimum medium temperature	-10 °C
Maximum medium temperature	60 °C
Standard nom. flow rate 1->2(S) max.	40 l/min
Standard nom. flow rate 1->2(S) min	0 l/min
Medium	Compressed air, filtered 40 µm (may be lubricated)