 



Fine filter LFMB-3/4-H-A

Part number: 162819

FESTO

With 1 µm filter cartridge, metal bowl guard.
Discontinued, available through 2008

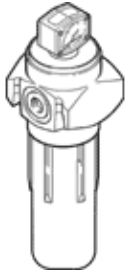

Data sheet

Feature	Value
Assembly position	Vertical +/- 5°
Grade of filtration	1 µm
Filter efficiency	99.9999 %
Condensate drain	fully automatic
Design structure	Fibre filter
Differential pressure display	Pressure gauge
Inlet pressure 1	0 ... 16 bar
Standard nominal flow rate	3,300 l/min
Operating medium	Filtered compressed air, 5 µm filtration
Storage temperature	-10 ... 60 °C
Medium temperature	1.5 ... 60 °C
Residual oil content	0.5 mg/m ³
Ambient temperature	-10 ... 60 °C
Mounting type	Optional Line installation with accessories
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	G3/4
Materials information for filter	Boron silicate fibre
Materials information, housing	Zinc die-casting
Materials information for bowl	Zinc die-casting