


# sub-base PAML-CP-186-HP3-G114

Part number: 1629296

FESTO

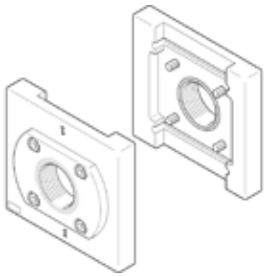

## Data sheet

Feature	Value
Size	186
Nominal diameter DN	54
Series	L
Operating pressure MPa	0 ... 5 MPa
Operating pressure	0 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Storage temperature	-10 ... 60 °C
Food-safe	See Supplementary material information
Medium temperature	5 ... 60 °C
Ambient temperature	5 ... 60 °C
Product weight	4,600 g
Pneumatic connection, port 1	G1 1/4
Pneumatic connection, port 2	G1 1/4
Materials note	Conforms to RoHS
Material of connecting plate	Wrought Aluminium alloy
Material seals	NBR
Material screws	Stainless steel