


connecting cable KVIA-10

Part number: 163961

FESTO

For analogue units.

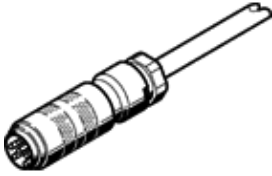

Data sheet

| Feature | Value |
|---|----------------------------------|
| Assembly position | Any |
| Operating voltage range AC | ≤ 250 V |
| Permissible current load | 1 A |
| Protection class | IP65 |
| Ambient temperature | -30 ... 80 °C |
| Product weight | 567 g |
| Electrical connection | Plug straight |
| Cable structure | 6x0,25 |
| Cable diameter | 8 mm |
| Cable length | 10 m |
| Mounting type | With sleeve nut |
| Materials information, housing | PBT |
| Materials information, cable sheaths | PVC |
| Material information for crimp connectors | Bronze Silver and gold plated |