


connecting cable

KRP-1-24-2,5

Part number: 165612
Product to be discontinued

FESTO

Connector socket for relay plate for valve terminal CPV with cable.
Type to be discontinued. Available until 2024. See Support Portal for alternative products.

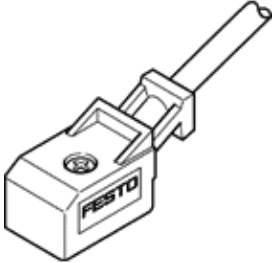

Data sheet

Feature	Value
Mounting type	with through hole
Assembly position	Any
Product weight	49 g
Electrical connection	2-pin Plug socket angled
Operating voltage range DC	≤ 26 V
Operating voltage range AC	≤ 20 V
Permissible current load	1 A
Cable length	2.5 m
Cable diameter	3.5 mm
Cable structure	2x0,25
Protection class	IP65
Ambient temperature	-10 ... 50 °C
CE mark (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Material cable sheath	PVC
Material housing	PUR
Material electrical contact	Bronze