

# Heavy-duty guide HD-40- -

Part number: 170027


FESTO

## Configurable

To configure first add product to the basket.

Depending on configuration, the technical data given on the data sheet and the relevant accessories might not match exactly for this product.

Products to be discontinued. Available until 2009.

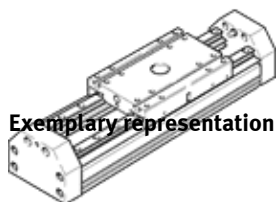

Exemplary representation

## Data sheet

~ConfIndependentDatasheet

Feature	Value
Size	40
Stroke	10 ... 2,110 mm
Assembly position	Any
Guide	Recirculating ball bearing guide
Design structure	Guide axis without drive unit
Max. speed	3 m/s
Corrosion resistance classification CRC	0
Ambient temperature	-10 ... 60 °C
Max. force Fy	5,400 N
Max. force Fz	5,600 N
Max. torque Mx	375 Nm
Max. torque My	560 Nm
Max. torque Mz	540 Nm
Moving mass	3,300 g
Moving mass with 0 mm stroke	3,300 g
Additional weight per 10 mm stroke	176 g
Basic weight for 0 mm stroke	11,800 g
Materials information for guide component	Steel
Materials information, housing	Wrought Aluminium alloy Anodised