


Setpoint module SPC200-2AI-U

Part number: 170177

FESTO

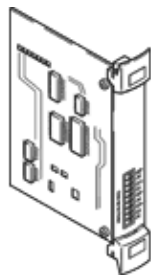

Data sheet

Feature	Value
Max. amplification error	0.2 %
Absolute reference voltage accuracy	0.4 %
Number of analogue inputs	2
Resolution	12 Bit
Input filter	Low pass, 16 Hz
Input voltage range	0 ... 10 V
Max. load current of the reference voltage source	8 mA
Max. offset error	1.5 mV
Min. input resistance	200 kOhm
Reference voltage	10 V
Typical current consumption, plug-in module	10 mA
Product weight	55 g
Absolute converter accuracy	< 0,3 % FS
Non-linearity	3 LSB
Electrical connection, inputs	Terminal strip 9-pin
Installation space	From 3 up