


# Digital I/O module SPC200-DIO

Part number: 170179

FESTO

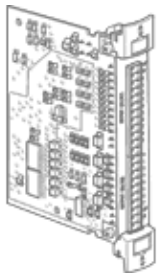

## Data sheet

Feature	Value
Fuse protection, output	Electronic Max. tripping current: 2 A Via sum of all outputs
Fuse protection for sensor supply voltage	Electronic
Response time, output	1.5 ms
Number of digital outputs	8
Number of digital inputs	10
Type of outputs	Per IEC 61131-2 Positive logic (PNP) Electrical isolation
Type of inputs	Per IEC 61131-2 Positive logic (PNP) No electrical isolation
Debouncing time, inputs	5 ms
Nominal operating voltage, DC outputs	24 V
Sensor supply	0.5 A from internal power supply
Current consumption, input	8 mA
Current-carrying capacity per output	250 mA
Typical current consumption, plug-in module	50 mA
Permissible voltage fluctuation, outputs	+/- 25 %
Product weight	62 g
Electrical connection, outputs	Terminal strip 10-pin
Electrical connection, inputs	Terminal strip 12-pin
Installation space	From 3 up