


# Blanking plug QSP14-PTB

Part number: 172987

FESTO

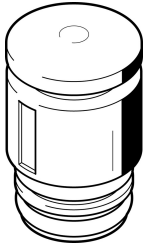

## Data sheet

Feature	Value
Size	Standard
Mounting position	optional
Design	Straight design
Size of pack	1
Operating pressure complete temperature range	0.095 MPa...1 MPa 0.95 bar...10 bar 13.775 psi...145 psi
Maritime classification	See certificate
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Product weight	2.7 g
Type of mounting	Mounting pin
Pneumatic connection, port 1	Cartridge 14 mm
Note on materials	RoHS-compliant
Material housing	PA
Material tubing seal	NBR