


# Valve terminal CPA10-VI

Part number: 173520

FESTO

Grid dimension 10 mm.

Depending on the configuration, the illustrations, the technical data on the data sheet and the relevant accessories might not exactly match this product.

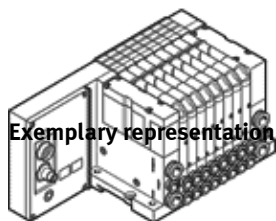

Exemplary representation

## Data sheet

~ConfIndependentDatasheet

| Feature                                 | Value   |
|---|---|
| Valve function                          | 2x3/2 open/closed, monostable<br>2x3/2 closed, monostable<br>2x3/2 open, monostable<br>5/2 monostable<br>5/2 bistable<br>5/3 pressurised<br>5/3 exhausted<br>5/3 closed |
| Standard nominal flow rate              | 300 l/min   |
| Operating pressure                      | -0.9 ... 10 bar   |
| Electrical connection                   | AS-Interface<br>Individual connection<br>Fieldbus<br>Multipol   |
| Max. number of valve positions          | 22  |
| Max. no. of pressure zones              | 11  |
| Electrical I/O system                   | Yes   |
| Ambient temperature                     | -5 ... 50 °C  |
| Width                                   | 10 mm   |
| Protection class                        | IP65  |
| Authorisation                           | C-Tick  |
| Grid dimension                          | 10 mm   |
| Type of actuation                       | electrical  |
| Valve terminal type                     | 12  |
| Design structure                        | Piston slide  |
| Pilot air supply                        | external<br>Internal  |
| Valve terminal structure                | modular and expandable  |
| Switching position indicator            | LED   |
| Pilot pressure                          | 3 ... 8 bar   |
| Nominal operating voltage DC            | 24 V  |
| CE mark (see declaration of conformity) | to EU directive for EMC   |
| Corrosion resistance classification CRC | 2   |
| Medium temperature                      | -5 ... 50 °C  |