

# branching module FRM-3/8-D-MINI-NPT

 

Part number: 173926

Classic - do not use for new projects

[Pneumatic manifold with 4 connections.](#)

[Modern alternatives can be found by entering the first four characters of the type code in the search field.](#)

FESTO

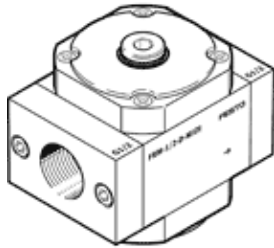

## Data sheet

| Feature  | Value   |
|--|---|
| Assembly position                                      | Any   |
| Design structure                                       | Branching module  |
| Operating pressure                                     | 0 ... 16 bar  |
| Standard nominal flow rate in main flow direction 1->2 | 2,900 l/min   |
| Operating medium                                       | Compressed air in accordance with ISO8573-1:2010 [7:-:-]<br>Inert gases |
| Corrosion resistance classification CRC                | 2 - Moderate corrosion stress   |
| PWIS conformity  | VDMA24364-B1/B2-L   |
| Storage temperature                                    | -10 ... 60 °C   |
| Air purity class at output                             | Compressed air in accordance with ISO8573-1:2010 [7:-:-]<br>Inert gases |
| Medium temperature                                     | -10 ... 60 °C   |
| Ambient temperature                                    | -10 ... 60 °C   |
| Product weight   | 207 g   |
| Pneumatic connection, port 1                           | 3/8 NPT   |
| Pneumatic connection, port 2                           | 3/8 NPT   |
| Pneumatic connection, port 3                           | G1/4  |
| Pneumatic connection, port 4                           | G1/4  |
| Materials note   | Conforms to RoHS  |
| Material housing                                       | Zinc die-casting  |