


# plug socket with cable KMEB-2-24-2,5-LED

Part number: 174844

FESTO

pre-assembled, for VUVB, MEBH, MOEBH valves and N2 solenoids.

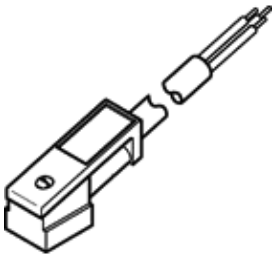

## Data sheet

Feature	Value
Switching position indicator	LED
Mounting type	On solenoid valve with M2.5 central screw
Assembly position	Any
Product weight	200 g
Electrical connection	4-pin Plug socket angled Plug pattern type C to EN 175301-803 Per DIN EN 175301-803
Nominal operating voltage DC	24 V
Protective earth connection	Available
Cable length	2.5 m
Cable diameter	6.2 mm
Cable structure	3x0,75
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 80 °C
CE mark (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material cable sheath	TPE-U(PUR)
Material housing	PA POM
Material electrical contact	Bronze