


Connecting cable KMP1-02-VI-12-10

Part number: 175588
Product to be discontinued

FESTO

For valve terminal VIMP-02, fully assembled for eight to twelve valve positions, 10 m long.

Type to be discontinued. Available until 2017. See Support Portal for alternative products.

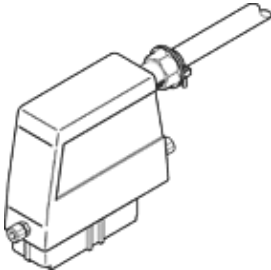

Data sheet

Feature	Value
Assembly position	Any
Operating voltage range AC	≤ 300 V
Operating voltage range DC	≤ 250 V
Permissible current load	4 A
Protection class	IP65
Ambient temperature with flexible cable installation	5 ... 70 °C
Ambient temperature	-30 ... 70 °C
Product weight	3,667 g
Electrical connection	25-pin Plug socket
Cable structure	25 x 0,75 mm ²
Cable diameter	13 mm
Cable length	10 m
Mounting type	With clamp strap
Materials information, housing	Die-cast light alloy
Materials information, cable sheaths	PE
Material information for crimp connectors	Copper alloy Silver plated