


Multi-pin plug distributor MPV-E/A08-M12

Part number: 177671

Product to be discontinued

Type to be discontinued. Available until 2017. See Support Portal for alternative products.

FESTO

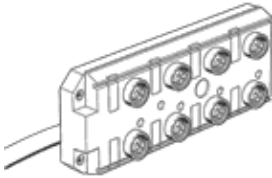

Data sheet

Feature	Value
Operating voltage range DC	10 ... 30 V
Current-carrying capacity per slot	4 A
Permissible current load	12 A
Protection class	IP67 in assembled condition to IEC 60529
Ambient temperature	-20 ... 80 °C
Product weight	200 g
Electrical connector technology, I/O	M12 5-pin
Mounting type	with through hole
Material information, socket	Brass Galvanised
Materials information, housing	TPE-U(PU)
Materials information, cable sheaths	TPE-U(PU)