


# distributor

## CQD-12/15/18/22

Part number: 177717

FESTO

With four blanking plugs.

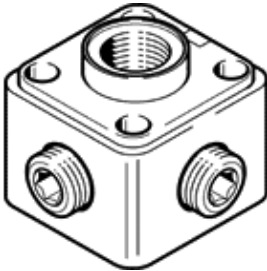

## Data sheet

Feature	Value
Nominal size	18.6 mm
Assembly position	Any
Container size	1
Operating pressure complete temperature range	-0.95 ... 7 bar
Temperature dependent operating pressure	-0.95 ... 15 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364 zone III
Medium temperature	-25 ... 75 °C
Ambient temperature	-25 ... 70 °C
Nominal tightening torque	2.5 Nm
Tolerance for nominal tightening torque	± 10 %
Number of outputs	4
Number of supply lines	1
Pneumatic connection, port 1	Female thread G1/2
Pneumatic connection, port 2	Female thread G1/2
Materials note	Conforms to RoHS
Material housing	POM