


# Pressure VIGZ-03-4,0-U

Part number: 178336

FESTO

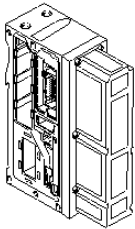

## Datasheet

Feature	Value
Type sub-base/manifold	Supply port Pl
Grid dimension	36 mm
Type of mounting sub-base	Screw
Type of mounting valve	Plug
Operating pressure min.	-0,9 bar
Operating pressure max.	10 bar
Ducted main ports	1+3+5
Ducted pilot ports	12+14
Ports 3,5 combined	No
Ports 12, 14 combined	No
Ports 82, 84 combined	No
Air connection type connection 1	Thread
Air connection type connections 3,5	Thread
Air connection type connections 12,14	Thread
Air connection type connections 82,84	Thread
Thread for port 1	G 3/8
Thread for ports 3, 5	G 1/2
Thread for ports 12, 14	G 1/8
Thread for ports 82, 84	G 1/4
Product weight	0,31 kg
Standard nominal flow rate 2 - 3	5800 l/min
Medium	geölte Druckluft