


coupling EAMC-B-19-24-6-9

Part number: 184263

FESTO

For electromechanical drive with servomotor

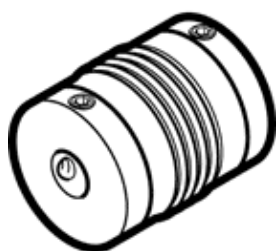

Data sheet

| Feature | Value |
|------------------------|------------------------|
| Holder diameter 1 | 6 mm |
| Holder diameter 2 | 9 mm |
| Size | 19 |
| Nominal length | 24 mm |
| Assembly position | Any |
| Max. speed | 8,000 1/min |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Ambient temperature | -25 ... 60 °C |
| Mass moment of inertia | 0.47 kgmm ² |
| Transferable torque | 1.5 Nm |
| Product weight | 12 g |
| Materials note | Conforms to RoHS |