


# Adsorption dryer LDF-H1-N1/4-110

Part number: 185675

FESTO

For dry and clean compressed air.

This product is only available if ordered from the Festo Corporation, USA.

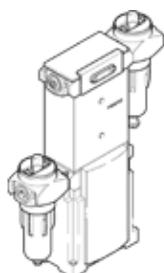

## Data sheet

Feature	Value
Assembly position	Vertical
Bowl guard	Metal bowl guard
Inlet pressure 1	4 ... 10.5 bar
Atmospheric dew point	-40 °C
Operating medium	Compressed air, filtered, unlubricated
CE symbol (see declaration of conformity)	according to EU-EMV guideline according to EU low voltage guideline
Corrosion resistance classification CRC	1
Medium temperature	2 ... 50 °C
Ambient temperature	2 ... 50 °C
Product weight	5,400 g
Mounting type	with through hole
Materials note	Free of copper and PTFE
Materials information, housing	Zinc die-casting