


Connecting cable KMP2-03-V-X-26

Part number: 18681

FESTO

The cable is available in lengths from 1 to 99 m.
Type to be discontinued. Available until 2012.

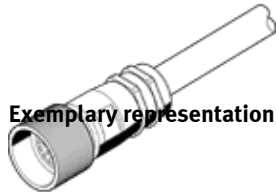

Exemplary representation

Data sheet

Feature	Value
Assembly position	Any
Operating voltage range AC	≤ 250 V
Operating voltage range DC	≤ 300 V
Permissible current load	7.5 A
Protection class	IP65
Ambient temperature	-5 ... 80 °C -20 ... 80 °C
Electrical connection	Plug socket 26-pin
Cable structure	26 x 0,75 mm ²
Cable diameter	15 mm
Mounting type	With sleeve nut
Colour code, core insulation	Black wires with consecutive white numbering from 1 to 26
Materials information for seals	CR Light and oil resistant
Materials information, housing	Copper alloy Nickel plated
Materials information, cable sheaths	PVC
Material information for crimp connectors	Copper alloy Gold plated