


# DUO cable KM12-DUO-M8-GDWD

Part number: 18688

FESTO

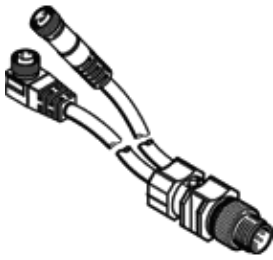

## Data sheet

Feature	Value
Assembly position	Any
Operating voltage range AC	≤ 60 V
Operating voltage range DC	≤ 75 V
Permissible current load	2.8 A
Protection class	IP67
Ambient temperature with flexible cable installation	-5 ... 70 °C
Ambient temperature	-30 ... 70 °C
Product weight	61 g
Electrical connection	Plug straight / socket straight M12x1 / M8 4-pin / 3-pin
Cable structure	2x(3x0,25)
Cable diameter	4.5 mm
Cable length	0.6 m
Mounting type	with through hole With threaded plug With sleeve nut
Materials information for locknut	Brass Nickel plated
Materials information, housing	PUR
Materials information, cable sheaths	PUR
Material information for crimp connectors	Brass Gold plated