


cable distributor ASI-KVT-FK-S

Part number: 18797

FESTO

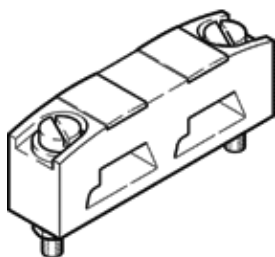

Data sheet

Feature	Value
Mounting type	with through hole
Assembly position	Any
Product weight	7.2 g
Operating voltage range DC	≤ 75 V
Operating voltage range AC	≤ 60 V
Permissible current load	3 A
Terminal cross-section	1.5 mm ²
Protection class	IP65
Ambient temperature with flexible cable installation	-5 ... 50 °C
Storage temperature	-30 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Material housing	PA
Material electrical contact	Bronze