


Local controller DLP-VSE-3-5/3-G-ASI

Part number: 188473

FESTO

For DLP cylinder series.

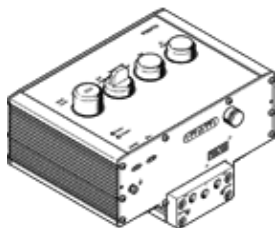

Data sheet

Feature	Value
Mounting type	Optional with through hole with accessories
Outdoor use	C1 - weather protected locations of use
Operating pressure	3 ... 8 bar
Nominal operating pressure	6 bar
Operating voltage range, DC AS-interface	26.5 ... 31.6 V
Operating voltage range, DC AS-interface, auxiliary power supply	20.4 ... 28.8 V
Max. current consumption	180 mA
CE mark (see declaration of conformity)	to EU directive for EMC
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Corrosion resistance classification CRC	3
Relative air humidity	5 - 100 % Condensing
Protection class	IP65 in assembled condition to IEC 60529
Ambient temperature	-5 ... 50 °C
Product weight	1,700 g
Materials information for cover	Wrought Aluminium alloy Anodised
Materials information for seals	NBR
Materials information, housing	Wrought Aluminium alloy Anodised
Screw material data	Steel Galvanised
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)