


# Manifold block VIGK-04-D-2

Part number: 18886

FESTO

For valve terminal

Products to be discontinued. Available until 2011.

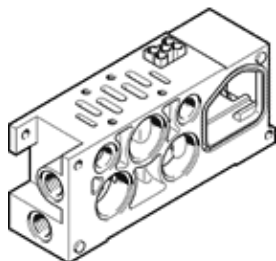

## Data sheet

Feature	Value
Based on the standard	ISO 5599-2
Max. number of valve positions	1
Operating pressure	-0.9 ... 16 bar
Operating medium	Filtered compressed air
Medium temperature	-10 ... 60 °C
Protection class	IP65
Ambient temperature	-10 ... 60 °C
Authorisation	UL - Recognized (OL)
Mounting method for sub-base	with through hole
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	G3/8
Pneumatic connection, port 3	G3/4
Pneumatic connection, port 4	G3/8
Pneumatic connection, port 5	G3/4
Materials information for sub-base	Aluminium die cast