

# Valve terminal VIFB-04-D-3-B


Part number: 18925

FESTO

with fieldbus connection, size 3.

Depending on the configuration, the illustrations, the technical data on the data sheet and the relevant accessories might not exactly match this product.

Products to be discontinued. Available until 2011.

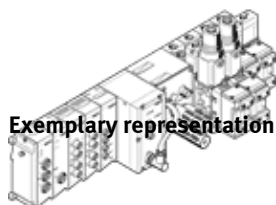

## Data sheet

~ConfIndependentDatasheet

Feature	Value
Valve function	5/2 monostable 5/2 bistable 5/3 pressurised 5/3 exhausted 5/3 closed
Standard nominal flow rate	4,500 l/min
Operating pressure	-0.9 ... 10 bar
Electrical connection	Fieldbus Integrated controller
Max. number of valve positions	16
Ambient temperature	-10 ... 60 °C
Protection class	IP65
Exhaust-air function	throttleable
Type of actuation	electrical
Valve terminal type	04
Design structure	Piston slide
Pilot air supply	external Internal
Valve terminal structure	modular and expandable
Switching position indicator	LED
Pilot pressure	2 ... 10 bar
Suitability for vacuum	Yes
Nominal operating voltage, AC	110 V
Nominal operating voltage DC	24 V
CE mark (see declaration of conformity)	to EU directive for EMC
Medium temperature	-10 ... 60 °C