


# Suction cup complete ESS-150-SN

Part number: 189326

FESTO

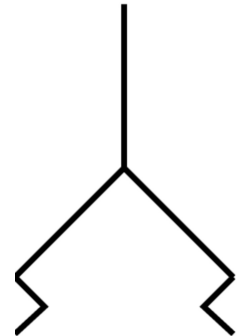

## Data sheet

Feature	Value
Min. workpiece radius	480 mm
Nominal size	10 mm
Suction cup diameter	150 mm
Suction cup volume	173.826 cm <sup>3</sup>
Position of connection	Top
Mounting position	optional
Correlation to suction-cup holder	Size 6
Suction cup shape	Round, flat
Operating pressure	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 psi...0 psi
Nominal operating pressure	-70 kPa -0.7 bar -10.15 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-A1-L
Suitable for use with food	See supplementary material information
Ambient temperature	-10 °C...70 °C
Holding force at nominal operating pressure	900 N
Lateral force at nominal operating pressure	675 N
Product weight	719 g
Type of mounting	Via vacuum port
Vacuum connection	M20x2
Colour	Black
Shore hardness	50 +/- 5

<b>Feature</b>	<b>Value</b>
Material screwed plug	NBR Nickel-plated steel Steel, galvanised and chrome-plated
Note on materials	RoHS-compliant
Material suction cup	NBR