


# addressing device ASI-PRG-ADR

Part number: 18959  
Product to be discontinued

FESTO

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

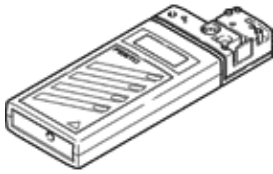

## Data sheet

Feature	Value
Materials note	Conforms to RoHS
Number of function keys	5
Fieldbus interface, protocol	AS-Interface SPEC 3.0
Permissible load current	100 mA
Short circuit strength	Yes
Overload withstand capability	Available
Fieldbus interface, number of pins/wires	5
Fieldbus interface, type of connection	Plug socket
Fieldbus interface, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Display	LCD-Display
Control elements	5 keys Membrane keypad
Dimensions W x L x H	34 mm x 210 mm x 80 mm
Nominal operating voltage DC	28 V
Power supply	Lithium battery
CE mark (see declaration of conformity)	to EU directive for EMC
PWIS conformity	VDMA24364-B2-L
Protection class	IP20
Ambient temperature	0 ... 40 °C
Product weight	610 g
Material housing	PA-reinforced