

Push-in T-fitting

QSMTL-1/16-5/32-U


Part number: 190819

FESTO

rotatable by 360°, male thread with external hexagon.

This product is only available if ordered from the Festo Corporation, USA.

Products to be discontinued. Available until 2011.

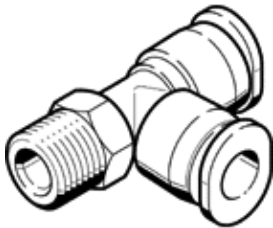

Data sheet

Feature	Value
Size	Mini
Nominal size	2 mm
Type of seal on screw-in stud	coating
Assembly position	Any
Container size	1
Design structure	Push/pull principle
Operating pressure	-0.95 ... 10 bar
Temperature dependent operating pressure	-0.95 ... 10 bar
Operating medium	Filtered compressed air Vacuum
Corrosion resistance classification CRC	1
Ambient temperature	-10 ... 60 °C
Authorisation	Germanischer Lloyd
Product weight	8.5 g
Number of outputs	2
Number of supply lines	1
Pneumatic connection, supply line	Male thread NPT1/16-27
Pneumatic connection, output	NPT1/8-27 for tubing, 3/16" outside diameter
Colour of release ring	Grey
Materials note	Conforms to RoHS
Materials information, housing	PBT
Release ring material data	POM
Materials information for tubing seal	NBR
Hose clamping segment material data	High alloy steel, non-corrosive