


multiple distributor QSYTF-1/4-5/16-U

Part number: 190835

FESTO

360° orientable, male and female thread with external hexagon.

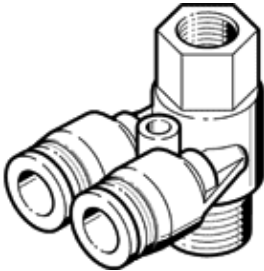

Data sheet

Feature	Value
Size	Standard
Nominal size	4.2 mm
Type of seal on screw-in stud	coating
Assembly position	Any
Design structure	Push/pull principle
Container size	1
Operating pressure complete temperature range	-0.95 ... 10 bar
Maritime classification	see certificate
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Product weight	45 g
Number of outputs	2
Number of supply lines	1
Pneumatic connection, port 1	Male thread 1/4 NPT Female thread 1/4 NPT
Pneumatic connection, port 2	for tubing, 5/16" outside diameter
Colour of release ring	Grey
Materials note	Conforms to RoHS
Material housing	PBT
Material hollow bolt	Nickel-plated brass
Material release ring	POM
Material of tubing seal	NBR
Material of tube retaining claw	High alloy steel, non-corrosive