

Ball valve QH-QS-1/4-U

Part number: 190883
Product to be discontinued


FESTO

with QS push-in connector.

This product is only available if ordered from the Festo Corporation, USA.

This type is suitable for vacuum.

Type to be discontinued. Available until 2016. See Support Portal for alternative products.

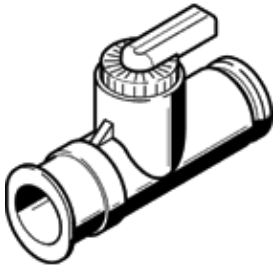

Data sheet

Feature	Value
Type of actuation	manual
Mounting type	Line installation
Nominal size	5 mm
Operating pressure	-1 ... 10 bar
Ambient temperature	0 ... 60 °C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Sealing principle	soft
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Product weight	45 g
Materials note	Conforms to RoHS