


# Pressure gauge MA-15-10-QS-3/8-U

Part number: 190938

FESTO

With display unit in psi.

This product is only available if ordered from the Festo Corporation, USA.

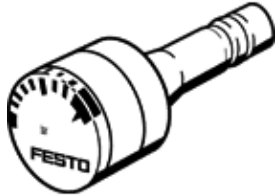

## Data sheet

Feature	Value
Indicating range [bar]	0 ... 10 bar
Conforms to standard	EN 837-1
Nominal size of pressure gauge	15
Design structure	Bourdon tube pressure gauge without measuring mechanism
Mounting type	Line installation
Operating medium	Inert gases Neutral fluids
Operating pressure	0 ... 10 bar
Alternating load factor	0.66
Measurement accuracy class	5
Protection class	IP53
Medium temperature	-20 ... 60 °C
Ambient temperature	-20 ... 60 °C
Materials note	Conforms to RoHS
Position of connection	Rear side central
Pneumatic connection	QS-3/8
Materials in contact with media	Brass
Materials information for screw-in stud	Brass
Materials information, housing	Steel
Materials info, viewing window	PC
Housing colour	Black
Product weight	10 g
Note on operating and pilot medium	No oxygen No acetylene