

# Non-return valve HBM-1/16-QS-5/32-U

Part number: 190946


FESTO

Flow rate from the QS plug connector to the male thread.

This product is only available if ordered from the Festo Corporation, USA.

This type is suitable for vacuum.

Products to be discontinued. Available until 2011.

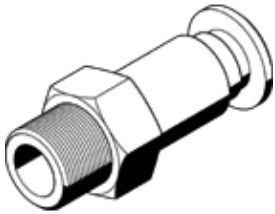

## Data sheet

Feature	Value
Valve function	Non-return function
Pneumatic connection, port 1	QS-5/32
Pneumatic connection, port 2	NPT1/16-27
Mounting type	Threaded
Operating pressure	-1 ... 10 bar
Ambient temperature	0 ... 60 °C
Materials information, housing	Brass
Operating medium	Compressed air, filtered, unlubricated Filtered, lubricated air
Product weight	12 g