


# vacuum suction cup

## ESV-80-ES

Part number: 191045

FESTO

Wearing part, easily replaceable

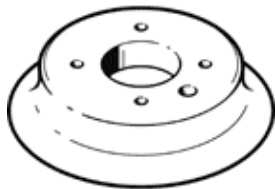

## Data sheet

Feature	Value
Min. workpiece radius	160 mm
suction cup diameter	80 mm
suction cup volume	44.18 cm <sup>3</sup>
Position of connection	on top
Assembly position	Any
Suction cup shape	Round, extra deep
Operating pressure MPa	-95 ... 0 kPa
Operating pressure	-0.95 ... 0 bar -13.775 ... 0 psi
Nominal operating pressure	-70 kPa -0.7 bar
Nominal operating pressure (psi)	-10.15 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
PWIS conformity	VDMA24364 zone III
Food-safe	See Supplementary material information
Ambient temperature	-30 ... 180 °C
Retention force at nominal operating pressure	275 N
Product weight	41 g
Colour	transparent
Shore hardness	50 +/- 5
Materials note	Conforms to RoHS
Material suction cup	VMQ (silicon)