


# Suction cup without connector ESV-30-BU

Part number: 191058

FESTO

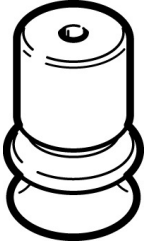

## Data sheet

Feature	Value
Height compensator for suction cup	8 mm
Min. workpiece radius	80 mm
Suction cup diameter	30 mm
Suction cup volume	4.07 cm <sup>3</sup>
Position of connection	Top
Mounting position	optional
Suction cup shape	Round bellows 1.5 convolutions
Operating pressure	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 psi...0 psi
Nominal operating pressure	-70 kPa -0.7 bar -10.15 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364 zone III
Suitable for use with food	See supplementary material information
Ambient temperature	-20 °C...60 °C
Holding force at nominal operating pressure	26.2 N
Product weight	3.6 g
Colour	Blue
Shore hardness	60 +/- 5
Note on materials	RoHS-compliant
Material suction cup	PUR