 



# vacuum filter ESF-3

Part number: 191202

FESTO

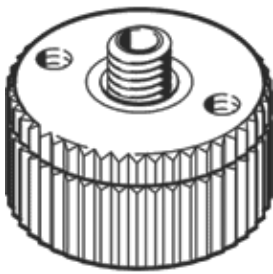

## Data sheet

Feature	Value
Assembly position	Any
Grade of filtration	10 µm
Operating pressure	-0.95 ... 4 bar
Flow rate at negative pressure of -0.075 MPa (-0.75 bar, -10.875 psi)	100 l/min
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:--]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	0 ... 60 °C
Product weight	9 g
Mounting type	with external (male) thread Via vacuum port
Pneumatic connection	M4
Vacuum connection	M4
Materials note	Conforms to RoHS
Material seals	NBR
Material filter	PVF
Material housing	Aluminium Nickel-plated brass