


plug SEA-4GS-7-2,5

Part number: 192008

FESTO

For valve terminals.

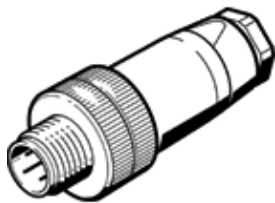

Data sheet

Feature	Value
Based on the standard	EN 61076-2-101 EN 61984
Mounting type	with threaded sleeve
Assembly position	Any
Product weight	18 g
Electrical connection	4-pin Plug pattern type A to EN 175301-803 M12x1 Straight plug / screw terminal
Operating voltage range DC	≤ 250 V
Operating voltage range AC	≤ 250 V
Acceptable current load at 40°C	4 A
Surge strength	2.5 kV
Cable gland connection	Pg7
Permissible cable diameter	2.5 ... 2.9 mm
Terminal cross-section	0.14 ... 0.5 mm ²
Protection class	IP65
Ambient temperature	-40 ... 85 °C
CE mark (see declaration of conformity)	to EU directive low-voltage devices
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material housing	PA
Housing colour	Black
Material of union nut	PA
Material electrical contact	Brass White bronze coated