


guide axis FDG-63- -

Part number: 192855
Product to be discontinued

FESTO

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

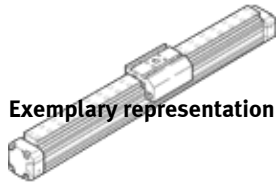

Exemplary representation

Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Size	63
Stroke	1 ... 4,500 mm
Assembly position	Any
Guide	Recirculating ball bearing guide
Design structure	Guide axis without drive unit
Max. speed	3 m/s
Corrosion resistance classification CRC	0 - No corrosion stress
Ambient temperature	-10 ... 60 °C
Materials note	Free of copper and PTFE
Material of guide component	Steel
Material housing	Wrought Aluminium alloy Anodised