


Standard cylinder DNA-5"- -

Part number: 193388

FESTO

This product is only available if ordered from the Festo Corporation, USA.
Depending on the configuration, the illustrations, the technical data on the data sheet and the relevant accessories might not exactly match this product.

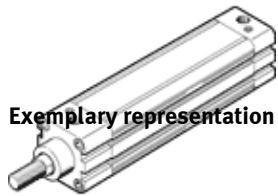

Data sheet

~ConfIndependentDatasheet

| Feature | Value |
|---|-------------------------|
| Stroke | 0.5 ... 80 " |
| Piston diameter | 5" |
| Based on the standard | ANSI/NFPA |
| Operating pressure | 0.6 ... 12 bar |
| Mode of operation | double-acting |
| Operating medium | Filtered compressed air |
| Corrosion resistance classification CRC | 1 |
| Ambient temperature | ≥ -20 °C |
| Materials information for cover | Wrought Aluminium alloy |
| Materials information, housing | Wrought Aluminium alloy |
| Materials information for piston rod | High alloy steel |